


WINDOW KIT, TYPE 4, 4X AND 12

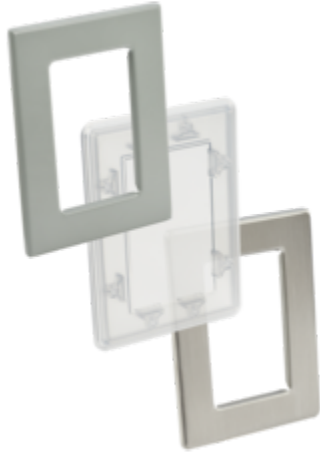

All Window kits are easy to install and require a simple rectangular enclosure cut-out. They are ideal for indoor and outdoor Type 3R, 4 and 12 applications.

Stainless Steel Window Kits are ideal for indoor and outdoor Type 3R, 4X and 12 applications where corrosion is a concern. Non-Metallic Window Kits are ideal for indoor and outdoor Type 3R, 4, 4X and 12 applications. They are also ideal for non-metallic enclosures where exterior metallic materials are not allowed and can accommodate up to .25-in. enclosure material thickness. When determining if a window kit will fit in a door or cover, be sure to allow for gaskets, data pockets, door handles, latch rods and other parts attached to the door or cover. Stainless Steel Window kits have a formed heavy gauge Type 304 stainless steel frame with a brushed finish. The clear window is made of .25-in. (6mm) impact-resistant polycarbonate material. They are ideal for indoor and outdoor Type 3R, 4X and 12 applications.

Non-Metallic Window kits are made of a single piece special polycarbonate blend, Makrolon, that has enhanced impact, UV, water exposure, absorption, and saturation resistance. They are ideal for indoor and outdoor Type 3R, 4, 4X and 12 applications. They are also ideal for non-metallic enclosures where exterior metallic materials are not allowed and can accommodate up to .25-in. enclosure material thickness.

All Window kits are easy to install and require a simple rectangular enclosure cut-out. All required hardware is furnished, along with assembly and cut- out instructions. The gasket material on all windows is resistant to oils, cutting fluids and many other liquids.

Window kits of the same size use the same interchangeable cut-out. Custom sizes for Steel and Stainless Steel Window Kits are available along with different finishes and gasket materials. Consult HOFFMAN for details.

FEATURES & BENEFITS

Window kits of the same size use the same interchangeable cut-out

The gasket material on all windows is resistant to oils, cutting fluids and many other liquids

All required hardware is furnished, along with assembly and cut- out instructions

The clear window of the Steel and Stainless Steel Window Kit is made of .25-in. (6mm) impact-resistant polycarbonate material

Non-Metallic Window kit are made of a single piece polycarbonate material

SPECIFICATIONS

Material Mild Steel

Table 1/1						
Catalog Number	Window Size	Cutout Size	Color	Color Code	Finish	Thickness
APWK95NF	229 x 140 mm	272 x 183 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK133NF	330 x 76 mm	373 x 119 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK1711NF	432 x 279 mm	475 x 322 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK175NF	432 x 140 mm	475 x 183 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK2315NF	584 x 381 mm	627 x 424 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK2919NF	737 x 483 mm	780 x 526 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK3523NF	889 x 584 mm	932 x 627 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK53NF	127 x 76 mm	170 x 119 mm	Gray	ANSI 61	Powder Coated	1.9 mm
APWK138NF	330 x 203 mm	373 x 246 mm	Gray	ANSI 61	Powder Coated	1.9 mm

Material Polycarbonate

Table 1/1					
Catalog Number	Window Size	Cutout Size	Color	Finish	Thickness
APWK116NFNM	279 x 152 mm	325 x 198 mm	Unpainted	Transparent	3 mm
APWK138NFNM	330 x 203 mm	375 x 248 mm	Unpainted	Transparent	3 mm
APWK53NFNM	127 x 76 mm	172 x 121 mm	Unpainted	Transparent	3 mm
APWK95NFNM	229 x 140 mm	274 x 185 mm	Unpainted	Transparent	3 mm

Material Stainless Steel 304

Table 1/1					
Catalog Number	Window Size	Cutout Size	Color	Finish	Thickness
APWK95NFSS	229 x 140 mm	272 x 183 mm	Unpainted	Brushed #3	1.9 mm

Catalog Number	Window Size	Cutout Size	Color	Finish	Thickness
APWK138NFSS	330 x 203 mm	373 x 246 mm	Unpainted	Brushed #3	1.98 mm
APWK1711NFSS	432 x 279 mm	475 x 322 mm	Unpainted	Brushed #3	1.98 mm
APWK2315NFSS	584 x 381 mm	627 x 424 mm	Unpainted	Brushed #3	1.98 mm
APWK2919NFSS	737 x 483 mm	780 x 526 mm	Unpainted	Brushed #3	1.98 mm
APWK53NFSS	127 x 76 mm	170 x 119 mm	Unpainted	Brushed #3	1.98 mm
APWK711NFSS	279 x 178 mm	221 x 322 mm	Unpainted	Brushed #3	1.98 mm
APWK715NFSS	381 x 178 mm	8.69 x 424 mm	Unpainted	Brushed #3	1.98 mm
APWK720NFSS	508 x 178 mm	221 x 551 mm	Unpainted	Brushed #3	1.98 mm
APWK724NFSS	610 x 178 mm	221 x 653 mm	Unpainted	Brushed #3	1.98 mm
APWK729NFSS	737 x 178 mm	221 x 780 mm	Unpainted	Brushed #3	1.98 mm

When determining if a window kit will fit in a door or cover, be sure to allow for gaskets, data pockets, door handles, latch rods and other parts attached to the door or cover.

North America

Tel +1.800.545.6258
 Fax +1.800.527.5703
 thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511
 Fax +32.16.213.604
 thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688
 Fax +86.21.5426.3167
 cn.thermal.info@nvent.com

Latin America

Tel +1.713.868.4800
 Fax +1.713.868.2333
 thermal.info@nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER