

 



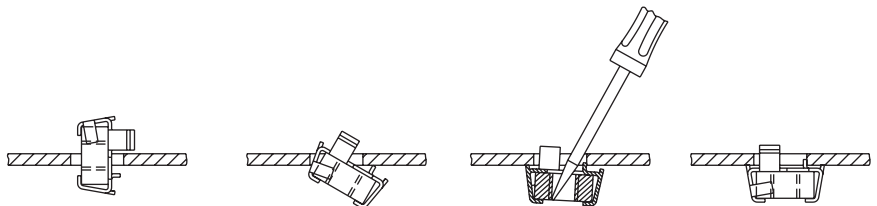
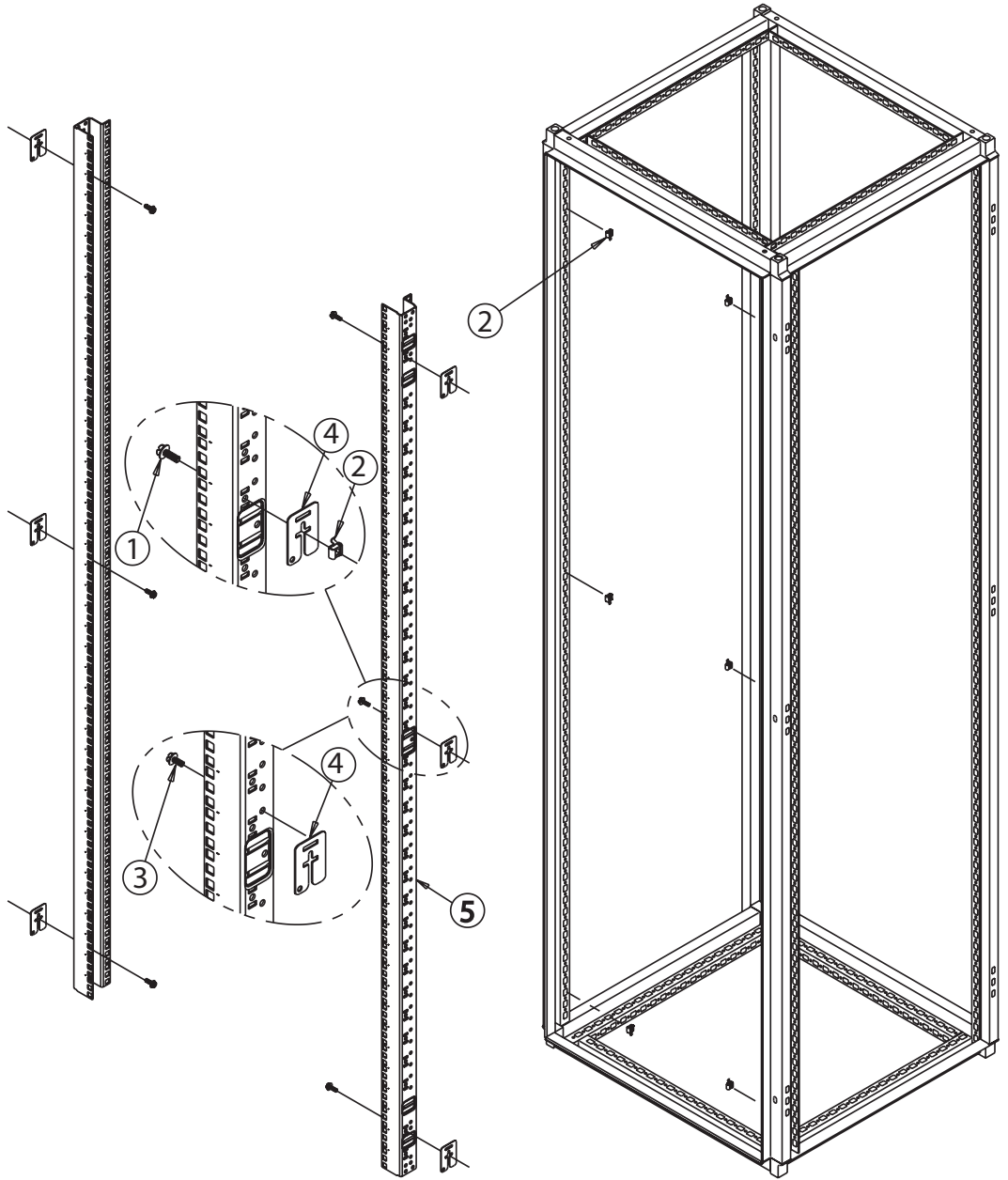
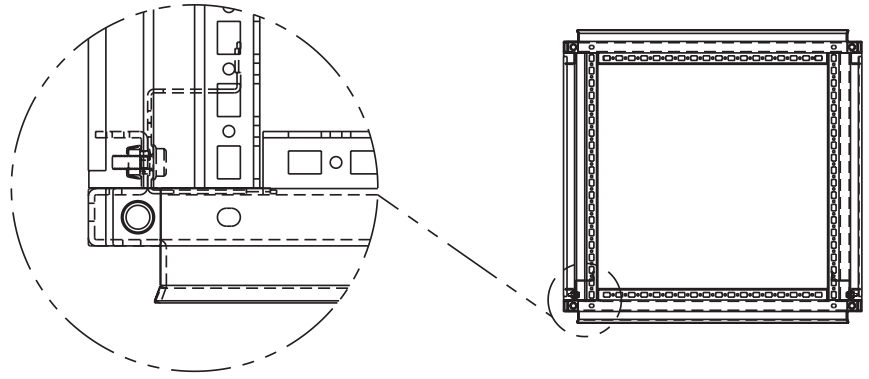
 
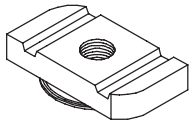


 




# PROLINE™



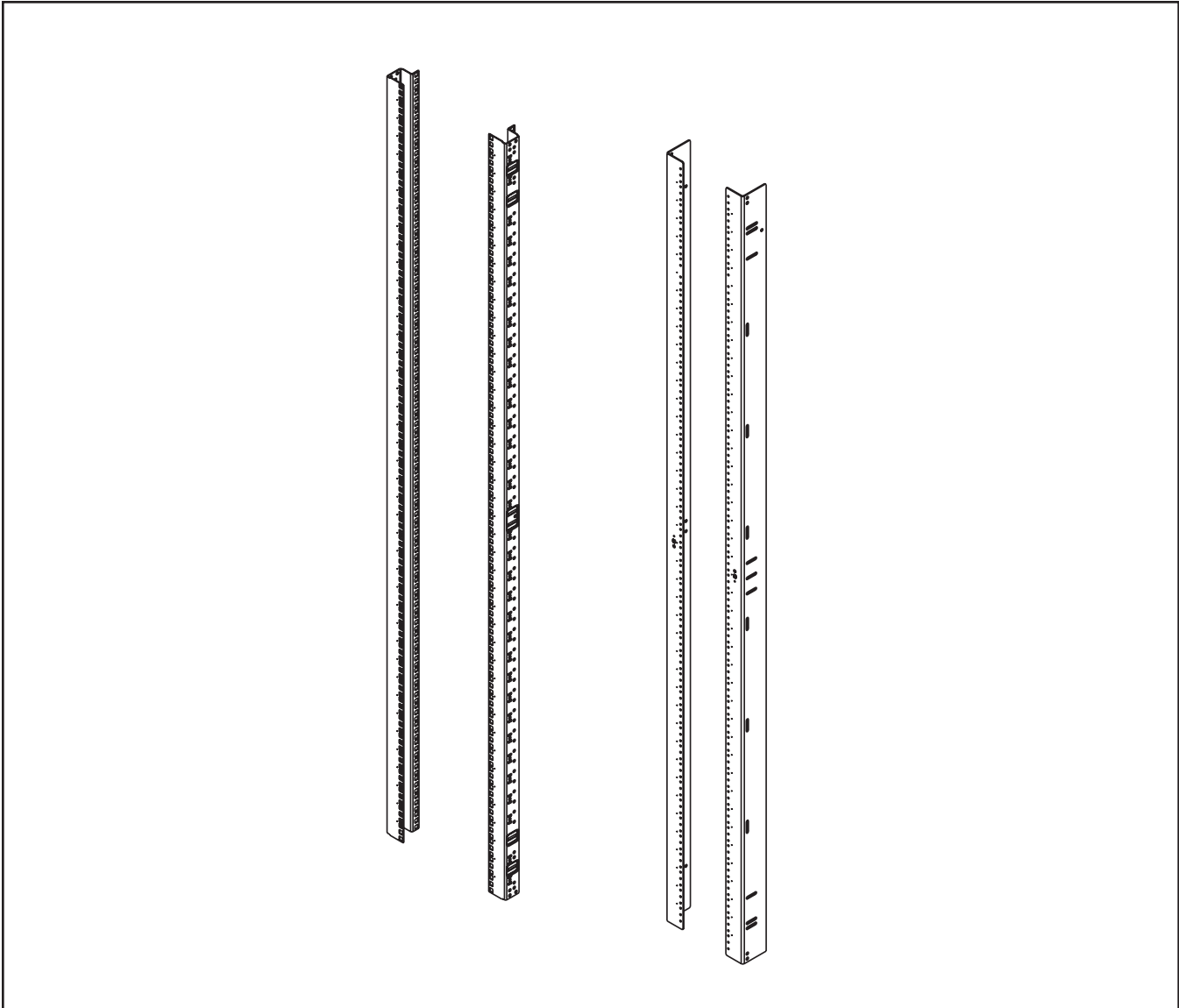


1	M6x20		(6x)
2	M6-1		(6x)
3	M5x10		(6x)
4			(6x)
5	PRAxxxxTH PRAxxxxTP		(2x)




1	M6x20		(6x)
2			(6x)
3	M5x10		(6x)
4			(6x)
5	PRAxxxxTHL1 PRAxxxxTPL1		(2x)

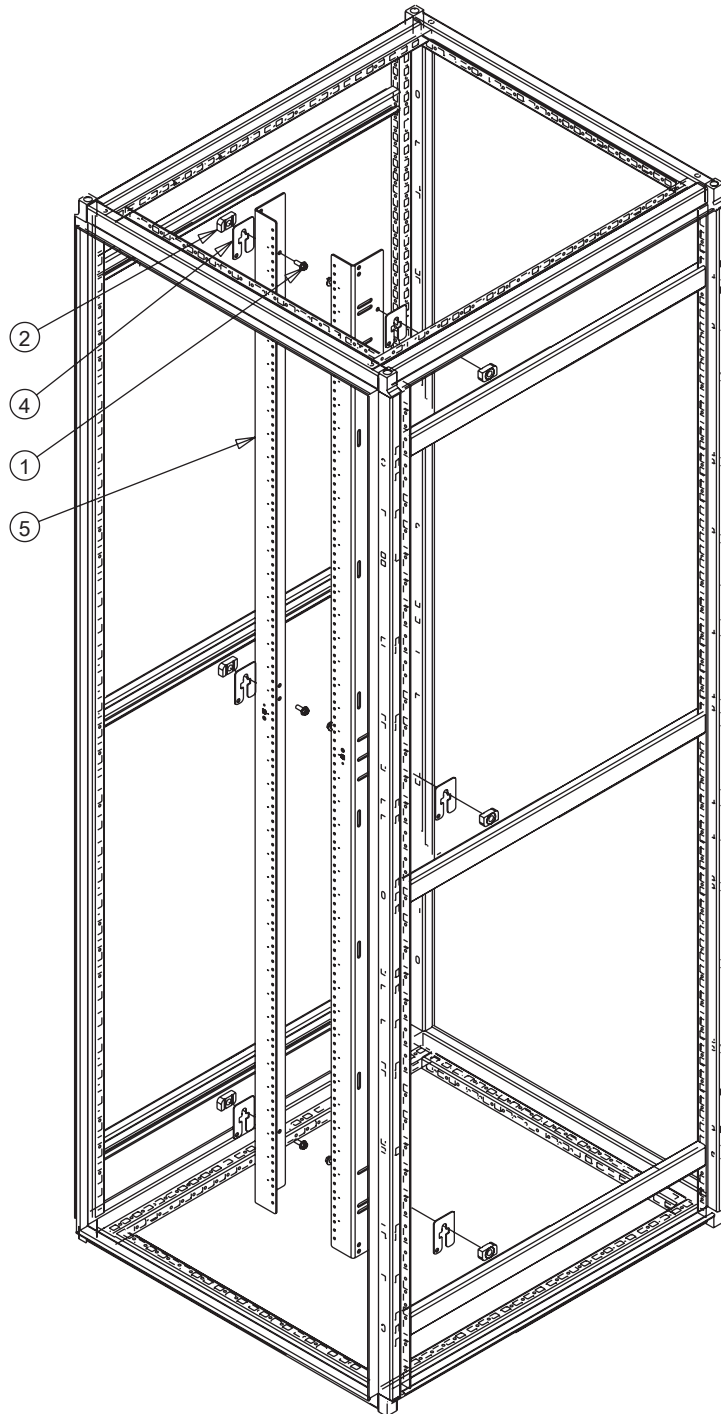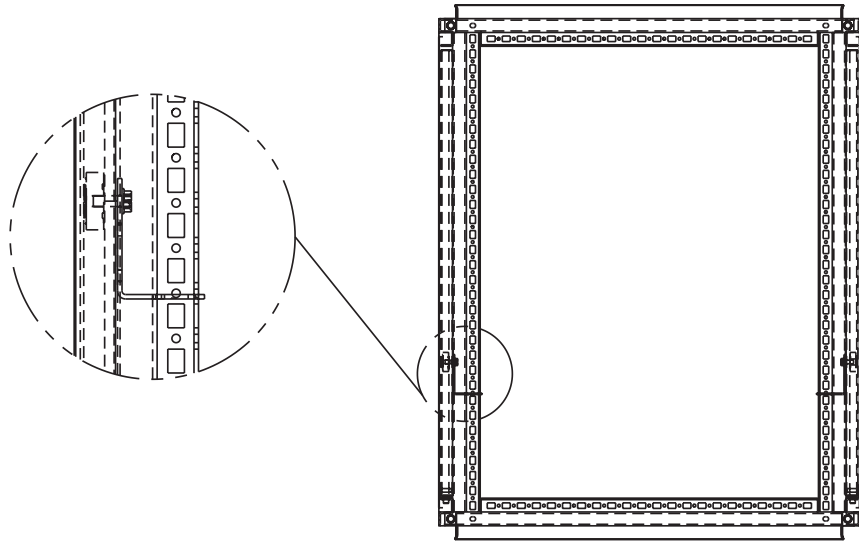

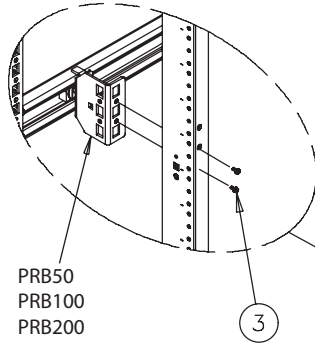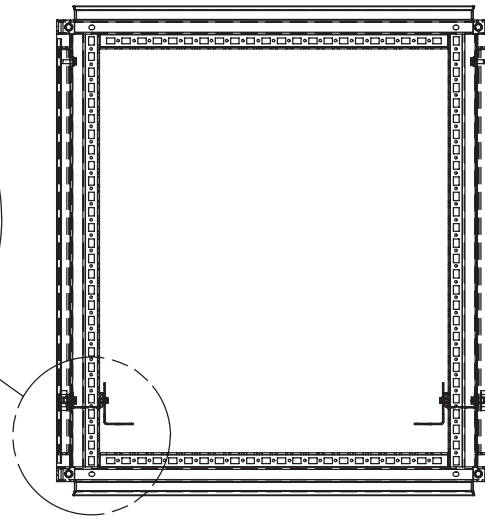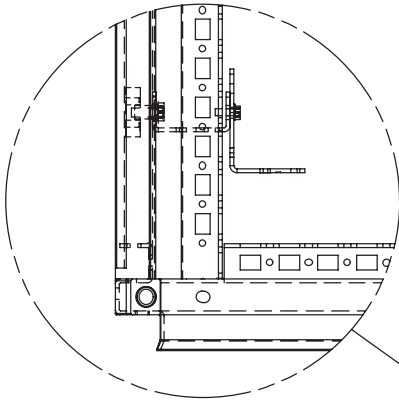

PRB50  
PRB100  
PRB200

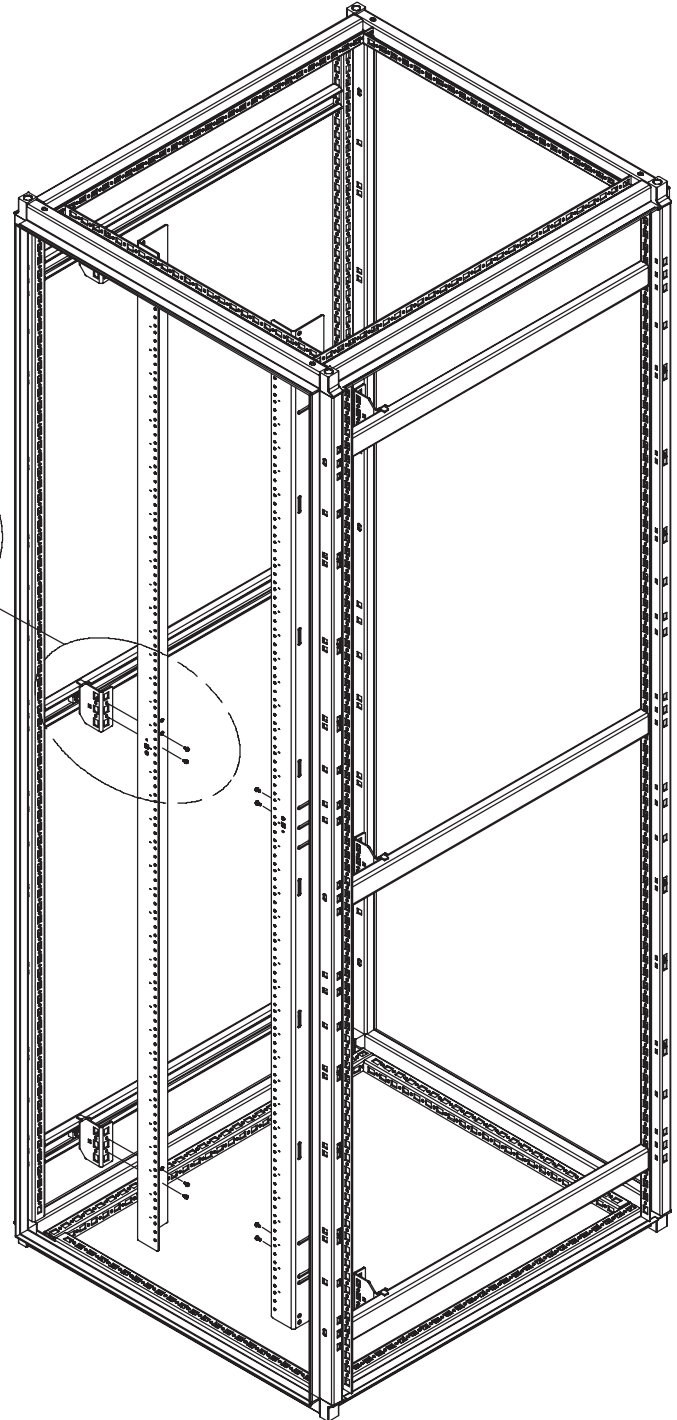

<p>PRB50 PRB100 PRB200</p>	
<p>PM6CN</p>	<p>M6-1</p>
<p>AS1032</p>	<p>10-32</p>