
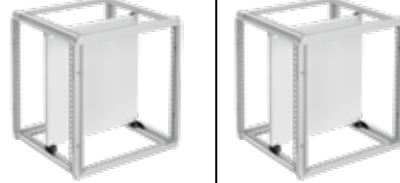



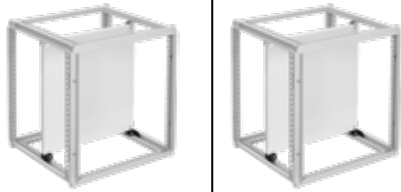



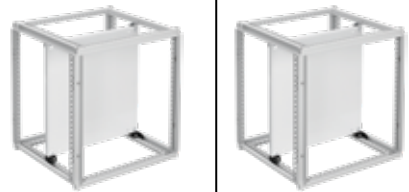




 
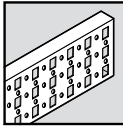
 
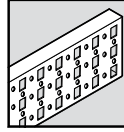
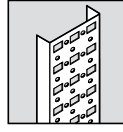





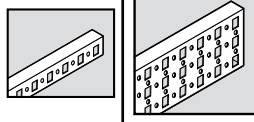
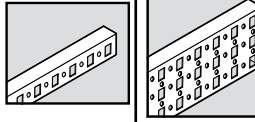
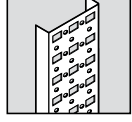

## SELECTION MATRIX: PANEL AND GRID MOUNTING



 
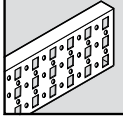
 
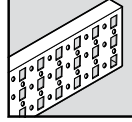
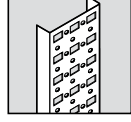

												
Frame Catalog No.	H (mm)	W (mm)	D (mm)	Bay Count	Full Subpanel (Painted)	Full Subpanel (Galvanized)	Full Side-Mount Subpanel (Painted)	Full Side-Mount Subpanel (Galvanized)	Joining Subpanel (Painted)	Joining Subpanel (Galvanized)	Swing-Out Subpanel (Painted)	Swing-Out Subpanel (Galvanized)
P2F664	600	600	400	Single	P2P66	P2P66G	P2PSM64	P2PSM64G	P2PJ6	P2PJ6G	P2PSO66	P2PSO66G
P2F666	600	600	600	Single	P2P66	P2P66G	P2PSM66	P2PSM66G	P2PJ6	P2PJ6G	P2PSO66	P2PSO66G
P2F688	600	800	800	Single	P2P68	P2P68G	P2PSM68	P2PSM68G	P2PJ6	P2PJ6G	P2PSO68	P2PSO68G
P2F864	800	600	400	Single	P2P86	P2P86G	N/A	N/A	P2PJ8	P2PJ8G	P2PSO86	P2PSO86G
P2F866	800	600	600	Single	P2P86	P2P86G	P2PSM86	P2PSM86G	P2PJ8	P2PJ8G	P2PSO86	P2PSO86G
P2F888	800	800	800	Single	P2P88	P2P88G	P2PSM88	P2PSM88G	P2PJ8	P2PJ8G	P2PSO88	P2PSO88G
P2F1064	1000	600	400	Single	P2P106	P2P106G	N/A	N/A	P2PJ10	P2PJ10G	P2PSO106	P2PSO106G
P2F1065	1000	600	500	Single	P2P106	P2P106G	P2PSM105	P2PSM105G	P2PJ10	P2PJ10G	P2PSO106	P2PSO106G
P2F1066	1000	600	600	Single	P2P106	P2P106G	P2PSM106	P2PSM106G	P2PJ10	P2PJ10G	P2PSO106	P2PSO106G
P2F1085	1000	800	500	Single	P2P108	P2P108G	P2PSM105	P2PSM105G	P2PJ10	P2PJ10G	P2PSO108	P2PSO108G
P2F1086	1000	800	600	Single	P2P108	P2P108G	P2PSM106	P2PSM106G	P2PJ10	P2PJ10G	P2PSO108	P2PSO108G
P2F1088	1000	800	800	Single	P2P108	P2P108G	P2PSM108	P2PSM108G	P2PJ10	P2PJ10G	P2PSO108	P2PSO108G
P2F10125	1000	1200	500	Double	P2P1012	P2P1012G	P2PSM105	P2PSM105G	P2PJ10	P2PJ10G	N/A	N/A
P2F1264	1200	600	400	Single	P2P126	P2P126G	N/A	N/A	P2PJ12	P2PJ12G	P2PSO126	P2PSO126G
P2F1265	1200	600	500	Single	P2P126	P2P126G	P2PSM125	P2PSM125G	P2PJ12	P2PJ12G	P2PSO126	P2PSO126G
P2F1266	1200	600	600	Single	P2P126	P2P126G	P2PSM126	P2PSM126G	P2PJ12	P2PJ12G	P2PSO126	P2PSO126G
P2F1285	1200	800	500	Single	P2P128	P2P128G	P2PSM125	P2PSM125G	P2PJ12	P2PJ12G	P2PSO128	P2PSO128G
P2F1286	1200	800	600	Single	P2P128	P2P128G	P2PSM126	P2PSM126G	P2PJ12	P2PJ12G	P2PSO128	P2PSO128G
P2F1288	1200	800	800	Single	P2P128	P2P128G	P2PSM128	P2PSM128G	P2PJ12	P2PJ12G	P2PSO128	P2PSO128G
P2F12125	1200	1200	500	Double	P2P1212	P2P1212G	P2PSM125	P2PSM125G	P2PJ12	P2PJ12G	N/A	N/A
P2F1465	1400	600	500	Single	P2P146	P2P146G	P2PSM145	P2PSM145G	P2PJ14	P2PJ14G	P2PSO146	P2PSO146G
P2F1466	1400	600	600	Single	P2P146	P2P146G	P2PSM146	P2PSM146G	P2PJ14	P2PJ14G	P2PSO146	P2PSO146G
P2F1468	1400	600	800	Single	P2P146	P2P146G	P2PSM148	P2PSM148G	P2PJ14	P2PJ14G	P2PSO146	P2PSO146G
P2F1485	1400	800	500	Single	P2P148	P2P148G	P2PSM145	P2PSM145G	P2PJ14	P2PJ14G	P2PSO148	P2PSO148G
P2F1486	1400	800	600	Single	P2P148	P2P148G	P2PSM146	P2PSM146G	P2PJ14	P2PJ14G	P2PSO148	P2PSO148G
P2F1488	1400	800	800	Single	P2P148	P2P148G	P2PSM148	P2PSM148G	P2PJ14	P2PJ14G	P2PSO148	P2PSO148G
P2F14125	1400	1200	500	Double	P2P1412	P2P1412G	P2PSM145	P2PSM145G	P2PJ14	P2PJ14G	N/A	N/A
P2F1664	1600	600	400	Single	P2P166	P2P166G	P2PSM164	P2PSM164G	P2PJ16	P2PJ16G	P2PSO166	P2PSO166G
P2F1665	1600	600	500	Single	P2P166	P2P166G	P2PSM165	P2PSM165G	P2PJ16	P2PJ16G	P2PSO166	P2PSO166G
P2F1666	1600	600	600	Single	P2P166	P2P166G	P2PSM166	P2PSM166G	P2PJ16	P2PJ16G	P2PSO166	P2PSO166G
P2F1668	1600	600	800	Single	P2P166	P2P166G	P2PSM168	P2PSM168G	P2PJ16	P2PJ16G	P2PSO166	P2PSO166G
P2F1684	1600	800	400	Single	P2P168	P2P168G	P2PSM164	P2PSM164G	P2PJ16	P2PJ16G	P2PSO168	P2PSO168G
P2F1685	1600	800	500	Single	P2P168	P2P168G	P2PSM165	P2PSM165G	P2PJ16	P2PJ16G	P2PSO168	P2PSO168G
P2F1686	1600	800	600	Single	P2P168	P2P168G	P2PSM166	P2PSM166G	P2PJ16	P2PJ16G	P2PSO168	P2PSO168G
P2F1688	1600	800	800	Single	P2P168	P2P168G	P2PSM168	P2PSM168G	P2PJ16	P2PJ16G	P2PSO168	P2PSO168G
P2F16104	1600	1000	400	Single	P2P1610	P2P1610G	P2PSM164	P2PSM164G	P2PJ16	P2PJ16G	N/A	N/A
P2F16106	1600	1000	600	Single	P2P1610	P2P1610G	P2PSM166	P2PSM166G	P2PJ16	P2PJ16G	N/A	N/A
P2F16124	1600	1200	400	Double	P2P1612	P2P1612G	P2PSM164	P2PSM164G	P2PJ16	P2PJ16G	N/A	N/A
P2F16125	1600	1200	500	Double	P2P1612	P2P1612G	P2PSM165	P2PSM165G	P2PJ16	P2PJ16G	N/A	N/A
P2F16126	1600	1200	600	Double	P2P1612	P2P1612G	P2PSM166	P2PSM166G	P2PJ16	P2PJ16G	N/A	N/A

												
Frame Catalog No.	H (mm)	W (mm)	D (mm)	Bay Count	Full Subpanel (Painted)	Full Subpanel (Galvanized)	Full Side-Mount Subpanel (Painted)	Full Side-Mount Subpanel (Galvanized)	Joining Subpanel (Painted)	Joining Subpanel (Galvanized)	Swing-Out Subpanel (Painted)	Swing-Out Subpanel (Galvanized)
P2F16128	1600	1200	800	Double	P2P1612	P2P1612G	P2PSM168	P2PSM168G	P2PJ16	P2PJ16G	N/A	N/A
P2F16164	1600	1600	400	Double	P2P1616	P2P1616G	P2PSM164	P2PSM164G	P2PJ16	P2PJ16G	N/A	N/A
P2F16165	1600	1600	500	Double	P2P1616	P2P1616G	P2PSM165	P2PSM165G	P2PJ16	P2PJ16G	N/A	N/A
P2F16166	1600	1600	600	Double	P2P1616	P2P1616G	P2PSM166	P2PSM166G	P2PJ16	P2PJ16G	N/A	N/A
P2F16168	1600	1600	800	Double	P2P1616	P2P1616G	P2PSM168	P2PSM168G	P2PJ16	P2PJ16G	N/A	N/A
P2F1845	1800	400	500	Single	P2P184	P2P184G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	N/A	N/A
P2F1846	1800	400	600	Single	P2P184	P2P184G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	N/A	N/A
P2F1864	1800	600	400	Single	P2P186	P2P186G	P2PSM184	P2PSM184G	P2PJ18	P2PJ18G	P2PSO186	P2PSO186G
P2F1865	1800	600	500	Single	P2P186	P2P186G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	P2PSO186	P2PSO186G
P2F1866	1800	600	600	Single	P2P186	P2P186G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	P2PSO186	P2PSO186G
P2F1868	1800	600	800	Single	P2P186	P2P186G	P2PSM188	P2PSM188G	P2PJ18	P2PJ18G	P2PSO186	P2PSO186G
P2F1884	1800	800	400	Single	P2P188	P2P188G	P2PSM184	P2PSM184G	P2PJ18	P2PJ18G	P2PSO188	P2PSO188G
P2F1885	1800	800	500	Single	P2P188	P2P188G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	P2PSO188	P2PSO188G
P2F1886	1800	800	600	Single	P2P188	P2P188G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	P2PSO188	P2PSO188G
P2F1888	1800	800	800	Single	P2P188	P2P188G	P2PSM188	P2PSM188G	P2PJ18	P2PJ18G	P2PSO188	P2PSO188G
P2F18104	1800	1000	400	Single	P2P1810	P2P1810G	P2PSM184	P2PSM184G	P2PJ18	P2PJ18G	N/A	N/A
P2F18105	1800	1000	500	Single	P2P1810	P2P1810G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	N/A	N/A
P2F18106	1800	1000	600	Single	P2P1810	P2P1810G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	N/A	N/A
P2F18108	1800	1000	800	Single	P2P1810	P2P1810G	P2PSM188	P2PSM188G	P2PJ18	P2PJ18G	N/A	N/A
P2F18124	1800	1200	400	Double	P2P1812	P2P1812G	P2PSM184	P2PSM184G	P2PJ18	P2PJ18G	N/A	N/A
P2F18125	1800	1200	500	Double	P2P1812	P2P1812G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	N/A	N/A
P2F18126	1800	1200	600	Double	P2P1812	P2P1812G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	N/A	N/A
P2F18128	1800	1200	800	Double	P2P1812	P2P1812G	P2PSM188	P2PSM188G	P2PJ18	P2PJ18G	N/A	N/A
P2F18164	1800	1600	400	Double	P2P1816	P2P1816G	P2PSM184	P2PSM184G	P2PJ18	P2PJ18G	N/A	N/A
P2F18165	1800	1600	500	Double	P2P1816	P2P1816G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	N/A	N/A
P2F18166	1800	1600	600	Double	P2P1816	P2P1816G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	N/A	N/A
P2F18168	1800	1600	800	Double	P2P1816	P2P1816G	P2PSM188	P2PSM188G	P2PJ18	P2PJ18G	N/A	N/A
P2F18185	1800	1800	500	Double	P2P1818	P2P1818G	P2PSM185	P2PSM185G	P2PJ18	P2PJ18G	N/A	N/A
P2F18186	1800	1800	600	Double	P2P1818	P2P1818G	P2PSM186	P2PSM186G	P2PJ18	P2PJ18G	N/A	N/A
P2F18188	1800	1800	800	Double	P2P1818	P2P1818G	P2PSM188	P2PSM188G	P2PJ18	P2PJ18G	N/A	N/A
P2F2045	2000	400	500	Single	P2P204	P2P204G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	N/A	N/A
P2F2046	2000	400	600	Single	P2P204	P2P204G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	N/A	N/A
P2F2064	2000	600	400	Single	P2P206	P2P206G	P2PSM204	P2PSM204G	P2PJ20	P2PJ20G	P2PSO206	P2PSO206G
P2F2065	2000	600	500	Single	P2P206	P2P206G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	P2PSO206	P2PSO206G
P2F2066	2000	600	600	Single	P2P206	P2P206G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	P2PSO206	P2PSO206G
P2F2068	2000	600	800	Single	P2P206	P2P206G	P2PSM208	P2PSM208G	P2PJ20	P2PJ20G	P2PSO206	P2PSO206G
P2F2084	2000	800	400	Single	P2P208	P2P208G	P2PSM204	P2PSM204G	P2PJ20	P2PJ20G	P2PSO208	P2PSO208G
P2F2085	2000	800	500	Single	P2P208	P2P208G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	P2PSO208	P2PSO208G
P2F2086	2000	800	600	Single	P2P208	P2P208G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	P2PSO208	P2PSO208G
P2F2088	2000	800	800	Single	P2P208	P2P208G	P2PSM208	P2PSM208G	P2PJ20	P2PJ20G	P2PSO208	P2PSO208G
P2F20810	2000	800	1000	Single	P2P208	P2P208G	P2PSM2010	P2PSM2010G	P2PJ20	P2PJ20G	P2PSO208	P2PSO208G

												
Frame Catalog No.	H (mm)	W (mm)	D (mm)	Bay Count	Full Subpanel (Painted)	Full Subpanel (Galvanized)	Full Side-Mount Subpanel (Painted)	Full Side-Mount Subpanel (Galvanized)	Joining Subpanel (Painted)	Joining Subpanel (Galvanized)	Swing-Out Subpanel (Painted)	Swing-Out Subpanel (Galvanized)
P2F20105	2000	1000	500	Single	P2P2010	P2P2010G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	N/A	N/A
P2F20106	2000	1000	600	Single	P2P2010	P2P2010G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	N/A	N/A
P2F20108	2000	1000	800	Single	P2P2010	P2P2010G	P2PSM208	P2PSM208G	P2PJ20	P2PJ20G	N/A	N/A
P2F20124	2000	1200	400	Double	P2P2012	P2P2012G	P2PSM204	P2PSM204G	P2PJ20	P2PJ20G	N/A	N/A
P2F20125	2000	1200	500	Double	P2P2012	P2P2012G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	N/A	N/A
P2F20126	2000	1200	600	Double	P2P2012	P2P2012G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	N/A	N/A
P2F20128	2000	1200	800	Double	P2P2012	P2P2012G	P2PSM208	P2PSM208G	P2PJ20	P2PJ20G	N/A	N/A
P2F20165	2000	1600	500	Double	P2P2016	P2P2016G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	N/A	N/A
P2F20166	2000	1600	600	Double	P2P2016	P2P2016G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	N/A	N/A
P2F20168	2000	1600	800	Double	P2P2016	P2P2016G	P2PSM208	P2PSM208G	P2PJ20	P2PJ20G	N/A	N/A
P2F20185	2000	1800	500	Double	P2P2018	P2P2018G	P2PSM205	P2PSM205G	P2PJ20	P2PJ20G	N/A	N/A
P2F20186	2000	1800	600	Double	P2P2018	P2P2018G	P2PSM206	P2PSM206G	P2PJ20	P2PJ20G	N/A	N/A
P2F20188	2000	1800	800	Double	P2P2018	P2P2018G	P2PSM208	P2PSM208G	P2PJ20	P2PJ20G	N/A	N/A
P2F2265	2200	600	500	Single	P2P226	P2P226G	P2PSM225	P2PSM225G	P2PJ22	P2PJ22G	P2PSO226	P2PSO226G
P2F2266	2200	600	600	Single	P2P226	P2P226G	P2PSM226	P2PSM226G	P2PJ22	P2PJ22G	P2PSO226	P2PSO226G
P2F2285	2200	800	500	Single	P2P228	P2P228G	P2PSM225	P2PSM225G	P2PJ22	P2PJ22G	P2PSO228	P2PSO228G
P2F2286	2200	800	600	Single	P2P228	P2P228G	P2PSM226	P2PSM226G	P2PJ22	P2PJ22G	P2PSO228	P2PSO228G
P2F2288	2200	800	800	Single	P2P228	P2P228G	P2PSM228	P2PSM228G	P2PJ22	P2PJ22G	P2PSO228	P2PSO228G
P2F22810	2200	800	1000	Single	P2P228	P2P228G	P2PSM2210	P2PSM2210G	P2PJ22	P2PJ22G	P2PSO228	P2PSO228G
P2F22105	2200	1000	500	Single	P2P2210	P2P2210G	P2PSM225	P2PSM225G	P2PJ22	P2PJ22G	N/A	N/A
P2F22106	2200	1000	600	Single	P2P2210	P2P2210G	P2PSM226	P2PSM226G	P2PJ22	P2PJ22G	N/A	N/A
P2F22108	2200	1000	800	Single	P2P2210	P2P2210G	P2PSM228	P2PSM228G	P2PJ22	P2PJ22G	N/A	N/A
P2F22125	2200	1200	500	Double	P2P2212	P2P2212G	P2PSM225	P2PSM225G	P2PJ22	P2PJ22G	N/A	N/A
P2F22126	2200	1200	600	Double	P2P2212	P2P2212G	P2PSM226	P2PSM226G	P2PJ22	P2PJ22G	N/A	N/A
P2F22128	2200	1200	800	Double	P2P2212	P2P2212G	P2PSM228	P2PSM228G	P2PJ22	P2PJ22G	N/A	N/A
P2F22165	2200	1600	500	Double	P2P2216	P2P2216G	P2PSM225	P2PSM225G	P2PJ22	P2PJ22G	N/A	N/A
P2F22166	2200	1600	600	Double	P2P2216	P2P2216G	P2PSM226	P2PSM226G	P2PJ22	P2PJ22G	N/A	N/A
P2F22168	2200	1600	800	Double	P2P2216	P2P2216G	P2PSM228	P2PSM228G	P2PJ22	P2PJ22G	N/A	N/A
P2F22185	2200	1800	500	Double	P2P2218	P2P2218G	P2PSM225	P2PSM225G	P2PJ22	P2PJ22G	N/A	N/A
P2F22186	2200	1800	600	Double	P2P2218	P2P2218G	P2PSM226	P2PSM226G	P2PJ22	P2PJ22G	N/A	N/A
P2F22188	2200	1800	800	Double	P2P2218	P2P2218G	P2PSM228	P2PSM228G	P2PJ22	P2PJ22G	N/A	N/A

																		
Frame Catalog No.	H (mm)	W (mm)	D (mm)	Bay Count	Center Upright	Grid Strap 1 Row (width)	Grid Strap 3 Row (width)	Grid Strap 1 Row (depth)	Grid Strap 3 Row (depth)	Vertical Grid Strap	Frame Shelf							
P2F664	600	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R6	P2ASHF64							
P2F666	600	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R6	P2ASHF66							
P2F688	600	800	800	Single	P2ACU6	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R6	P2ASHF88							
P2F864	800	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R8	P2ASHF64							
P2F866	800	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R8	P2ASHF66							
P2F888	800	800	800	Single	P2ACU8	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R8	P2ASHF88							
P2F1064	1000	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R10	P2ASHF64							
P2F1065	1000	600	500	Single	N/A	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R10	P2ASHF65							
P2F1066	1000	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R10	P2ASHF66							
P2F1085	1000	800	500	Single	P2ACU10	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R10	P2ASHF85							
P2F1086	1000	800	600	Single	P2ACU10	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R10	P2ASHF86							
P2F1088	1000	800	800	Single	P2ACU10	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R10	P2ASHF88							
P2F10125	1000	1200	500	Double	P2ACU10	P2G1R13	P2G3R13	P2G1R5	P2G3R5	P2GV3R10	N/A							
P2F1264	1200	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R12	P2ASHF64							
P2F1265	1200	600	500	Single	N/A	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R12	P2ASHF65							
P2F1266	1200	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R12	P2ASHF66							
P2F1285	1200	800	500	Single	P2ACU12	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R12	P2ASHF85							
P2F1286	1200	800	600	Single	P2ACU12	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R12	P2ASHF86							
P2F1288	1200	800	800	Single	P2ACU12	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R12	P2ASHF88							
P2F12125	1200	1200	500	Double	P2ACU12	P2G1R13	P2G3R13	P2G1R5	P2G3R5	P2GV3R12	N/A							
P2F1465	1400	600	500	Single	N/A	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R14	P2ASHF65							
P2F1466	1400	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R14	P2ASHF66							
P2F1468	1400	600	800	Single	N/A	P2G1R7	P2G3R7	P2G1R8	P2G3R8	P2GV3R14	P2ASHF68							
P2F1485	1400	800	500	Single	P2ACU14	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R14	P2ASHF85							
P2F1486	1400	800	600	Single	P2ACU14	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R14	P2ASHF86							
P2F1488	1400	800	800	Single	P2ACU14	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R14	P2ASHF88							
P2F14125	1400	1200	500	Double	P2ACU14	P2G1R13	P2G3R13	P2G1R5	P2G3R5	P2GV3R14	N/A							
P2F1664	1600	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R16	P2ASHF64							
P2F1665	1600	600	500	Single	N/A	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R16	P2ASHF65							
P2F1666	1600	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R16	P2ASHF66							
P2F1668	1600	600	800	Single	N/A	P2G1R7	P2G3R7	P2G1R8	P2G3R8	P2GV3R16	P2ASHF68							
P2F1684	1600	800	400	Single	P2ACU16	P2G1R9	P2G3R9	P2G1R4	P2G3R4	P2GV3R16	P2ASHF84							
P2F1685	1600	800	500	Single	P2ACU16	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R16	P2ASHF85							
P2F1686	1600	800	600	Single	P2ACU16	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R16	P2ASHF86							
P2F1688	1600	800	800	Single	P2ACU16	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R16	P2ASHF88							
P2F16104	1600	1000	400	Single	P2ACU16	P2G1R11	P2G3R11	P2G1R4	P2G3R4	P2GV3R16	P2ASHF104							
P2F16106	1600	1000	600	Single	P2ACU16	P2G1R11	P2G3R11	P2G1R6	P2G3R6	P2GV3R16	P2ASHF106							
P2F16124	1600	1200	400	Double	P2ACU16	P2G1R13	P2G3R13	P2G1R4	P2G3R4	P2GV3R16	N/A							
P2F16125	1600	1200	500	Double	P2ACU16	P2G1R13	P2G3R13	P2G1R5	P2G3R5	P2GV3R16	N/A							
P2F16126	1600	1200	600	Double	P2ACU16	P2G1R13	P2G3R13	P2G1R6	P2G3R6	P2GV3R16	N/A							
P2F16128	1600	1200	800	Double	P2ACU16	P2G1R13	P2G3R13	P2G1R8	P2G3R8	P2GV3R16	N/A							
P2F16164	1600	1600	400	Double	P2ACU16	P2G1R17	P2G3R17	P2G1R4	P2G3R4	P2GV3R16	N/A							

												
Frame Catalog No.	H (mm)	W (mm)	D (mm)	Bay Count	Center Upright	Grid Strap 1 Row (width)	Grid Strap 3 Row (width)	Grid Strap 1 Row (depth)	Grid Strap 3 Row (depth)	Vertical Grid Strap	Frame Shelf	
P2F16165	1600	1600	500	Double	P2ACU16	P2G1R17	P2G3R17	P2G1R5	P2G3R5	P2GV3R16	N/A	
P2F16166	1600	1600	600	Double	P2ACU16	P2G1R17	P2G3R17	P2G1R6	P2G3R6	P2GV3R16	N/A	
P2F16168	1600	1600	800	Double	P2ACU16	P2G1R17	P2G3R17	P2G1R8	P2G3R8	P2GV3R16	N/A	
P2F1845	1800	400	500	Single	N/A	P2G1R5	P2G3R5	P2G1R5	P2G3R5	P2GV3R18	P2ASHF45	
P2F1846	1800	400	600	Single	N/A	P2G1R5	P2G3R5	P2G1R6	P2G3R6	P2GV3R18	P2ASHF46	
P2F1864	1800	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R18	P2ASHF64	
P2F1865	1800	600	500	Single	N/A	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R18	P2ASHF65	
P2F1866	1800	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R18	P2ASHF66	
P2F1868	1800	600	800	Single	N/A	P2G1R7	P2G3R7	P2G1R8	P2G3R8	P2GV3R18	P2ASHF68	
P2F1884	1800	800	400	Single	P2ACU18	P2G1R9	P2G3R9	P2G1R4	P2G3R4	P2GV3R18	P2ASHF84	
P2F1885	1800	800	500	Single	P2ACU18	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R18	P2ASHF85	
P2F1886	1800	800	600	Single	P2ACU18	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R18	P2ASHF86	
P2F1888	1800	800	800	Single	P2ACU18	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R18	P2ASHF88	
P2F18104	1800	1000	400	Single	P2ACU18	P2G1R11	P2G3R11	P2G1R4	P2G3R4	P2GV3R18	P2ASHF104	
P2F18105	1800	1000	500	Single	P2ACU18	P2G1R11	P2G3R11	P2G1R5	P2G3R5	P2GV3R18	P2ASHF105	
P2F18106	1800	1000	600	Single	P2ACU18	P2G1R11	P2G3R11	P2G1R6	P2G3R6	P2GV3R18	P2ASHF106	
P2F18108	1800	1000	800	Single	P2ACU18	P2G1R11	P2G3R11	P2G1R8	P2G3R8	P2GV3R18	P2ASHF108	
P2F18124	1800	1200	400	Double	P2ACU18	P2G1R13	P2G3R13	P2G1R4	P2G3R4	P2GV3R18	N/A	
P2F18125	1800	1200	500	Double	P2ACU18	P2G1R13	P2G3R13	P2G1R5	P2G3R5	P2GV3R18	N/A	
P2F18126	1800	1200	600	Double	P2ACU18	P2G1R13	P2G3R13	P2G1R6	P2G3R6	P2GV3R18	N/A	
P2F18128	1800	1200	800	Double	P2ACU18	P2G1R13	P2G3R13	P2G1R8	P2G3R8	P2GV3R18	N/A	
P2F18164	1800	1600	400	Double	P2ACU18	P2G1R17	P2G3R17	P2G1R4	P2G3R4	P2GV3R18	N/A	
P2F18165	1800	1600	500	Double	P2ACU18	P2G1R17	P2G3R17	P2G1R5	P2G3R5	P2GV3R18	N/A	
P2F18166	1800	1600	600	Double	P2ACU18	P2G1R17	P2G3R17	P2G1R6	P2G3R6	P2GV3R18	N/A	
P2F18168	1800	1600	800	Double	P2ACU18	P2G1R17	P2G3R17	P2G1R8	P2G3R8	P2GV3R18	N/A	
P2F18185	1800	1800	500	Double	P2ACU18	P2G1R19	P2G3R19	P2G1R5	P2G3R5	P2GV3R18	N/A	
P2F18186	1800	1800	600	Double	P2ACU18	P2G1R19	P2G3R19	P2G1R6	P2G3R6	P2GV3R18	N/A	
P2F18188	1800	1800	800	Double	P2ACU18	P2G1R19	P2G3R19	P2G1R8	P2G3R8	P2GV3R18	N/A	
P2F2045	2000	400	500	Single	N/A	P2G1R5	P2G3R5	P2G1R5	P2G3R5	P2GV3R20	P2ASHF45	
P2F2046	2000	400	600	Single	N/A	P2G1R5	P2G3R5	P2G1R6	P2G3R6	P2GV3R20	P2ASHF46	
P2F2064	2000	600	400	Single	N/A	P2G1R7	P2G3R7	P2G1R4	P2G3R4	P2GV3R20	P2ASHF64	
P2F2065	2000	600	500	Single	N/A	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R20	P2ASHF65	
P2F2066	2000	600	600	Single	N/A	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R20	P2ASHF66	
P2F2068	2000	600	800	Single	N/A	P2G1R7	P2G3R7	P2G1R8	P2G3R8	P2GV3R20	P2ASHF68	
P2F2084	2000	800	400	Single	P2ACU20	P2G1R9	P2G3R9	P2G1R4	P2G3R4	P2GV3R20	P2ASHF84	
P2F2085	2000	800	500	Single	P2ACU20	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R20	P2ASHF85	
P2F2086	2000	800	600	Single	P2ACU20	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R20	P2ASHF86	
P2F2088	2000	800	800	Single	P2ACU20	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R20	P2ASHF88	
P2F20810	2000	800	1000	Single	P2ACU20	P2G1R9	P2G3R9	P2G1R10	P2G3R10	P2GV3R20	P2ASHF810	
P2F20105	2000	1000	500	Single	P2ACU20	P2G1R11	P2G3R11	P2G1R5	P2G3R5	P2GV3R20	P2ASHF105	
P2F20106	2000	1000	600	Single	P2ACU20	P2G1R11	P2G3R11	P2G1R6	P2G3R6	P2GV3R20	P2ASHF106	
P2F20108	2000	1000	800	Single	P2ACU20	P2G1R11	P2G3R11	P2G1R8	P2G3R8	P2GV3R20	P2ASHF108	

											
Frame Catalog No.	H (mm)	W (mm)	D (mm)	Bay Count	Center Upright	Grid Strap 1 Row (width)	Grid Strap 3 Row (width)	Grid Strap 1 Row (depth)	Grid Strap 3 Row (depth)	Vertical Grid Strap	Frame Shelf
P2F20124	2000	1200	400	Double	P2ACU20	P2G1R13	P2G3R13	P2G1R4	P2G3R4	P2GV3R20	N/A
P2F20125	2000	1200	500	Double	P2ACU20	P2G1R13	P2G3R13	P2G1R5	P2G3R5	P2GV3R20	N/A
P2F20126	2000	1200	600	Double	P2ACU20	P2G1R13	P2G3R13	P2G1R6	P2G3R6	P2GV3R20	N/A
P2F20128	2000	1200	800	Double	P2ACU20	P2G1R13	P2G3R13	P2G1R8	P2G3R8	P2GV3R20	N/A
P2F20165	2000	1600	500	Double	P2ACU20	P2G1R17	P2G3R17	P2G1R5	P2G3R5	P2GV3R20	N/A
P2F20166	2000	1600	600	Double	P2ACU20	P2G1R17	P2G3R17	P2G1R6	P2G3R6	P2GV3R20	N/A
P2F20168	2000	1600	800	Double	P2ACU20	P2G1R17	P2G3R17	P2G1R8	P2G3R8	P2GV3R20	N/A
P2F20185	2000	1800	500	Double	P2ACU20	P2G1R19	P2G3R19	P2G1R5	P2G3R5	P2GV3R20	N/A
P2F20186	2000	1800	600	Double	P2ACU20	P2G1R19	P2G3R19	P2G1R6	P2G3R6	P2GV3R20	N/A
P2F20188	2000	1800	800	Double	P2ACU20	P2G1R19	P2G3R19	P2G1R8	P2G3R8	P2GV3R20	N/A
P2F2265	2200	600	500	Single	N/A	P2G1R5	P2G3R5	P2G1R5	P2G3R5	P2GV3R22	P2ASHF65
P2F2266	2200	600	600	Single	N/A	P2G1R5	P2G3R5	P2G1R6	P2G3R6	P2GV3R22	P2ASHF66
P2F2268	2200	600	800	Single	N/A	P2G1R5	P2G3R5	P2G1R8	P2G3R8	P2GV3R22	P2ASHF68
P2F2285	2200	800	500	Single	P2ACU22	P2G1R7	P2G3R7	P2G1R5	P2G3R5	P2GV3R22	P2ASHF85
P2F2286	2200	800	600	Single	P2ACU22	P2G1R7	P2G3R7	P2G1R6	P2G3R6	P2GV3R22	P2ASHF86
P2F2288	2200	800	800	Single	P2ACU22	P2G1R7	P2G3R7	P2G1R8	P2G3R8	P2GV3R22	P2ASHF88
P2F22810	2200	800	1000	Single	P2ACU22	P2G1R7	P2G3R7	P2G1R10	P2G3R10	P2GV3R22	P2ASHF810
P2F22105	2200	1000	500	Single	P2ACU22	P2G1R9	P2G3R9	P2G1R5	P2G3R5	P2GV3R22	P2ASHF105
P2F22106	2200	1000	600	Single	P2ACU22	P2G1R9	P2G3R9	P2G1R6	P2G3R6	P2GV3R22	P2ASHF106
P2F22108	2200	1000	800	Single	P2ACU22	P2G1R9	P2G3R9	P2G1R8	P2G3R8	P2GV3R22	P2ASHF108
P2F22125	2200	1200	500	Double	P2ACU22	P2G1R11	P2G3R11	P2G1R5	P2G3R5	P2GV3R22	N/A
P2F22126	2200	1200	600	Double	P2ACU22	P2G1R11	P2G3R11	P2G1R6	P2G3R6	P2GV3R22	N/A
P2F22128	2200	1200	800	Double	P2ACU22	P2G1R11	P2G3R11	P2G1R8	P2G3R8	P2GV3R22	N/A
P2F22165	2200	1600	500	Double	P2ACU22	P2G1R15	P2G3R15	P2G1R5	P2G3R5	P2GV3R22	N/A
P2F22166	2200	1600	600	Double	P2ACU22	P2G1R15	P2G3R15	P2G1R6	P2G3R6	P2GV3R22	N/A
P2F22168	2200	1600	800	Double	P2ACU22	P2G1R15	P2G3R15	P2G1R8	P2G3R8	P2GV3R22	N/A
P2F22185	2200	1800	500	Double	P2ACU22	P2G1R17	P2G3R17	P2G1R5	P2G3R5	P2GV3R22	N/A
P2F22186	2200	1800	600	Double	P2ACU22	P2G1R17	P2G3R17	P2G1R6	P2G3R6	P2GV3R22	N/A
P2F22188	2200	1800	800	Double	P2ACU22	P2G1R17	P2G3R17	P2G1R8	P2G3R8	P2GV3R22	N/A