

Syspend Sanitary HMI System



HOFFMAN

COMPREHENSIVE HMI SOLUTION FOR DEMANDING SANITARY ENVIRONMENTS



CLEAN DESIGN AND VERSATILE CONFIGURATION OPTIONS



Syspend Sanitary HMI System is an HMI enclosure and suspension system set — designed to reliably enclose, protect and suspend lightweight HMI devices up to 90 lbs. in challenging sanitary environments. Offering superior Type 4X and IP69K protection in high pressure, high temperature washdown applications, Syspend is designed with minimal bacteria catch points and no exterior bolts, set screws, or obtrusive hardware when bracket covers are used.

KEY FEATURES

- **Reversible 20-degree sloped top and slanted flange trough collar** prohibit pooling of water on top of and along top edge of enclosure opening
- **Unique Syspend-LOK fitting system** provides a multi-gasketed labyrinth to prevent water from entering the suspension system for secure installation with leveling capability
- **Superior washdown protection** with concealed one-piece closed-cell silicone gasketing that is easily replaceable
- **304 stainless steel construction** provides corrosion resistance and ease of cleaning
- **Integrated side handles** allow easy repositioning of enclosure
- **Optional low-profile cover for base** provides secure attachment to wall, floor or machine with 330-degree rotation and easy leveling capability

APPLICATIONS INCLUDE:

- Food and beverage
- Pharmaceutical
- Packaging

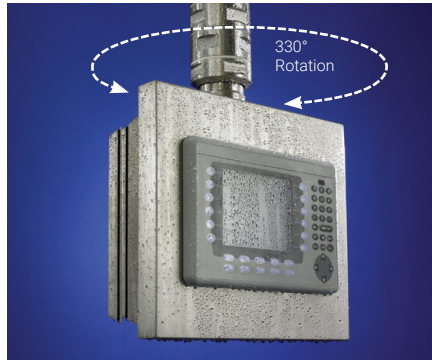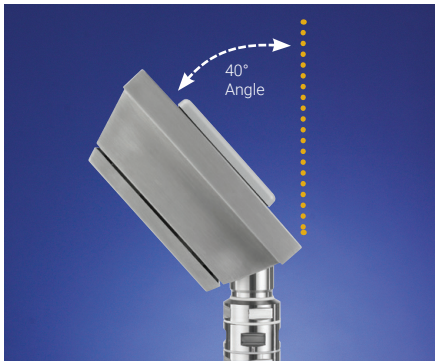

Ergonomic positioning



System load capacity varies by configuration. Reference the Syspend Sanitary HMI System Specification Sheet for the Load Capacity Graph and configuration suggestions.

VERSATILE FUNCTIONALITY FOR YOUR APPLICATION

The Syspend Sanitary HMI System provides versatile functionality with a host of robust features and configuration options.

- Modular design, with multiple tube lengths and straight, L and U-shaped tubes, allows for application versatility
- 330° rotation of joints for easy repositioning
- Syspend-LOK fittings attach without set screws to minimize bacteria catch points, providing a secure installation with leveling capability
- Full range of enclosure modifications are available

North America

Minneapolis, MN
Tel: +1.763.421.2240
Mexico City, Mexico
Tel: +52.55.5280.1449
Toronto, Canada
Tel: +1.416.289.2770

South America

Sao Paulo, Brazil
Tel: +55.11.5184.2100
Boitura, Brazil
Tel: +55.15.3363.9148

Europe

Betschdorf, France
Tel. +33.3.88.90.64.90
Straubenhardt, Germany
Tel: +49.7082.794.0
Dzierzoniow, Poland
Tel: +48.74.64.63.900
Assago, Italy
Tel: +39.02.5776151.224

Middle East & India

Dubai, United Arab Emirates
Tel: +971.4.378.1700
Bangalore, India
Tel: +91.80.6715.2001

Asia

Shanghai, P.R. China
Tel: +86.21.2412.6943
Singapur
Tel: +65.6768.5800
Shin-Yokohama, Japan
Tel: +81.45.476.0271
Seoul, Korea
Tel: +82.2.2129.7755
Qingdao
Tel: +86.532.8771.6101



nVent.com

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER