

nVent HOFFMAN 3D Configurator



FASTER AND EASIER TO DESIGN,
BUILD AND ORDER

DESIGNING, BUILDING AND ORDERING A HOFFMAN PROLINE G2 MODULAR ENCLOSURE HAS NEVER BEEN EASIER

With the HOFFMAN 3D Configurator you can select from multiple options to build a standard or custom modular enclosure. This state-of-the-art tool features an interactive 3D model, visual selections, and over 1800 mix-and-match components. Your end result: a 3D interactive model of your customized enclosure and completed Bill of Materials (BOM). All this without the hassle of finding part numbers.

Design - Quickly mix and match internal and external components or select one of the pre-packaged options and modify from there.

Build - Choose paint and finish options, select lifting provisions, add thermal management and other accessories.

Order - When you are finished creating your solution, automatically generate the BOM, submit your RFQ and receive a quote in 24 hours.



STATE-OF-THE-ART FUNCTIONALITY:

- Rotate your enclosure to view from any angle
- Move internal components or holes and cutouts to desired locations
- Transparent views allow for exploring internal components
- Open and close the door

ADDITIONAL FEATURES:

- Create joined/bayed enclosure configurations
- Add holes and cutouts
- Select cooling options
- Choose paint color and finish
- Add additional accessories
- Virtual packages: start with a package tailored for your application and modify as desired
- Embedded rules ensure you get a complete solution

HOFFMAN 3D CONFIGURATOR

CONFIGURE YOUR SOLUTION

SELECT A TYPE AND SIZE

- Choose from Standard (Mild Steel), EMC Protected or Disconnect
- Select the height, width and depth needed for your application
- Or start with a pre-defined package

EXTERIOR COMPONENTS


- Add doors or covers
- Select a top and base
- Select from various options for each side (doors, covers or barrier panel)

INTERIOR COMPONENTS

- Select subpanels and racks
- Add shelves, grid straps, lights and other accessories

VIEW YOUR ENCLOSURE

- Explode the view at any point to see the various parts that have been added
- View the parts list at any time
- Add your configured enclosure to the Project List on the website and submit to request a quote

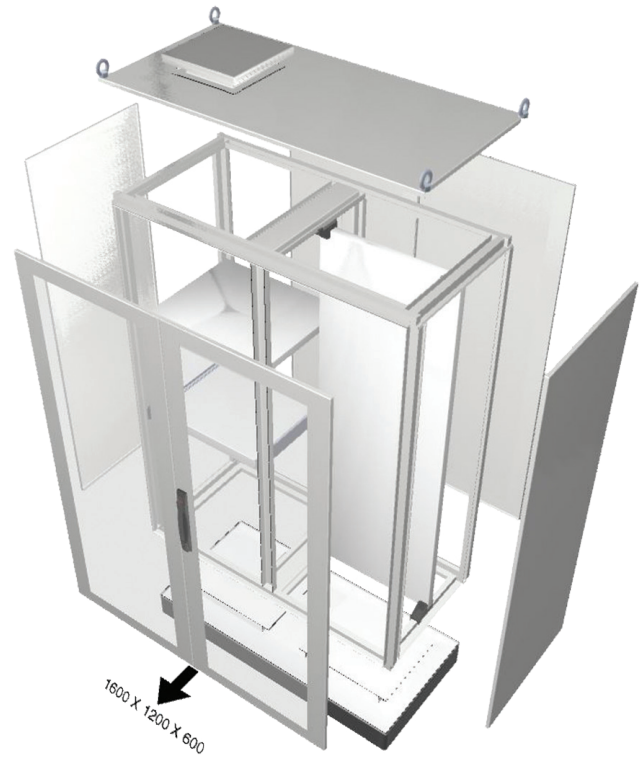

North America

Minneapolis, MN

Tel: +1.763.421.2240

Mexico City, Mexico

Tel: +52.55.5280.1449

Toronto, Canada

Tel: +1.416.289.2770

South America

Sao Paulo, Brazil

Tel: +55.11.5184.2100

Boitura, Brazil

Tel: +55.15.3363.9148

Europe

Betschdorf, France

Tel: +33.3.88.90.64.90

Straubenhardt, Germany

Tel: +49.7082.794.0

Dzierzoniow, Poland

Tel: +48.74.64.63.900

Assago, Italy

Tel: +39.02.5776151.224

Middle East & India

Dubai, United Arab Emirates

Tel: +971.4.378.1700

Bangalore, India

Tel: +91.80.6715.2001

Asia

Shanghai, P.R. China

Tel: +86.21.2412.6943

Singapur

Tel: +65.6768.5800

Shin-Yokohama, Japan

Tel: +81.45.476.0271

Seoul, Korea

Tel: +82.2.2129.7755

Qingdao

Tel: +86.532.8771.6101



nVent.com

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER